

**KB12-PP-AS**

Linear Ball Bearing

Linear ball bearings KB...-PP-AS, machined range, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

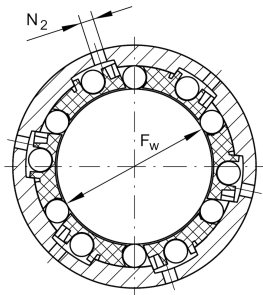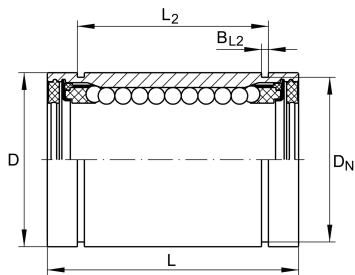

Your current product variant

Size code	12
-----------	----

Main Dimensions & Performance Data

F _w	12 mm	Bore diameter
	+0,008/0	Tolerance
D	22 mm	Outside diameter
	h5	Tolerance
L	32 mm	Length
	h12	Tolerance
C _{min}	540 N	Load capacity dyn.
C _{0 min}	385 N	Load capacity stat.
C _{max}	640 N	Load capacity dyn.
C _{0 max}	570 N	Load capacity stat.
≈m	36,24 g	Weight

Mounting dimensions

L ₂	22,6 mm	
	H13	Tolerance
B _{L2}	1,3 mm	
D _N	21 mm	
N ₂	1,5 mm	
	5	Number of rows balls