

**KB16-PP-AS**

Linear Ball Bearing

Linear ball bearings KB...-PP-AS, machined range, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

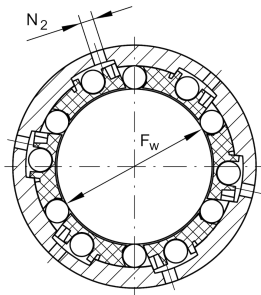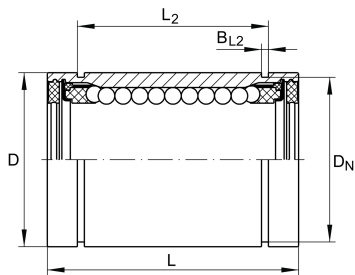

Your current product variant

Size code	16
-----------	----

Main Dimensions & Performance Data

F _W	16 mm	Bore diameter
	+0,009/-0,001	Tolerance
D	26 mm	Outside diameter
	h5	Tolerance
L	36 mm	Length
	h12	Tolerance
C _{min}	710 N	Load capacity dyn.
C _{0 min}	530 N	Load capacity stat.
C _{max}	840 N	Load capacity dyn.
C _{0 max}	780 N	Load capacity stat.
≈m	47,25 g	Weight

Mounting dimensions

L ₂	24,6 mm	
	H13	Tolerance
B _{L2}	1,3 mm	
D _N	24,9 mm	
N ₂	2 mm	
	5	Number of rows balls