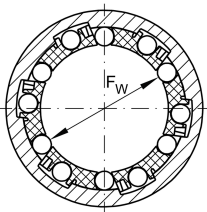
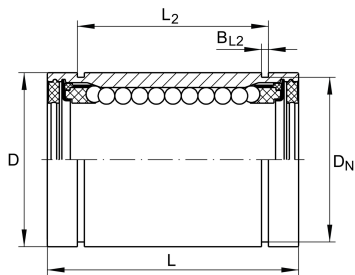
**KB20-PP** **Linear Ball Bearing**

Linear ball bearings KB...-PP, machined range, sealed on all sides, corrosion-resistant design possible

Technical information**Your current product variant**

Size code 20

Main Dimensions & Performance Data

F _W	20 mm	Bore diameter
	+0,009/-0,001	Tolerance
D	32 mm	Outside diameter
	h5	Tolerance
L	45 mm	Length
	h12	Tolerance
C _{min}	1.570 N	Load capacity dyn.
C _{0 min}	1.230 N	Load capacity stat.
C _{max}	1.660 N	Load capacity dyn.
C _{0 max}	1.570 N	Load capacity stat.
≈m	88,99 g	Weight

Mounting dimensions

L ₂	31,2 mm	
	H13	Tolerance
B _{L2}	1,6 mm	
D _N	30,3 mm	
N ₂	2 mm	
	6	Number of rows balls