

**KB20-PP-AS**

Linear Ball Bearing

Linear ball bearings KB...-PP-AS, machined range, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

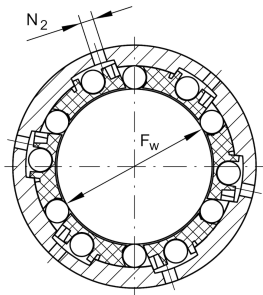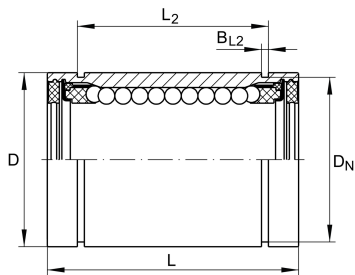

Your current product variant

Size code	20
-----------	----

Main Dimensions & Performance Data

F _w	20 mm	Bore diameter
	+0,009/-0,001	Tolerance
D	32 mm	Outside diameter
	h5	Tolerance
L	45 mm	Length
	h12	Tolerance
C _{min}	1.570 N	Load capacity dyn.
C _{0 min}	1.230 N	Load capacity stat.
C _{max}	1.660 N	Load capacity dyn.
C _{0 max}	1.570 N	Load capacity stat.
≈m	87,89 g	Weight

Mounting dimensions

L ₂	31,2 mm	
	H13	Tolerance
B _{L2}	1,6 mm	
D _N	30,3 mm	
N ₂	2 mm	
	6	Number of rows balls