

**KB25-PP-AS**

Linear Ball Bearing

Linear ball bearings KB...-PP-AS, machined range, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

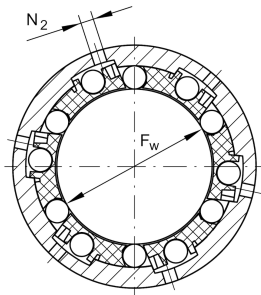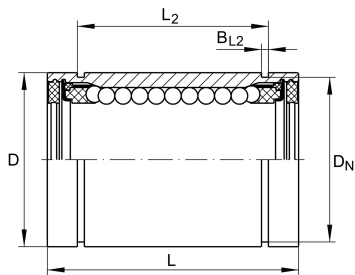

Your current product variant

Size code	25
-----------	----

Main Dimensions & Performance Data

F _w	25 mm	Bore diameter
	+0,011/-0,001	Tolerance
D	40 mm	Outside diameter
	h5	Tolerance
L	58 mm	Length
	h12	Tolerance
C _{min}	2.800 N	Load capacity dyn.
C _{0 min}	2.220 N	Load capacity stat.
C _{max}	2.950 N	Load capacity dyn.
C _{0 max}	2.850 N	Load capacity stat.
≈m	157,74 g	Weight

Mounting dimensions

L ₂	43,7 mm	
	H13	Tolerance
B _{L2}	1,85 mm	
D _N	37,5 mm	
N ₂	2,5 mm	
	6	Number of rows balls