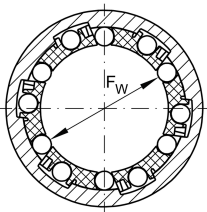
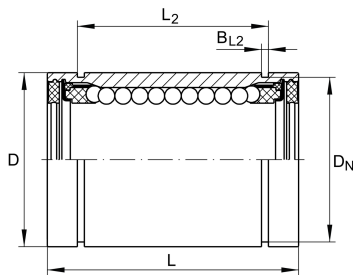
**KB30-PP** **Linear Ball Bearing**

Linear ball bearings KB...-PP, machined range, sealed on all sides, corrosion-resistant design possible

Technical information**Your current product variant**

Size code 30

Main Dimensions & Performance Data

F _W	30 mm	Bore diameter
	+0,011/-0,001	Tolerance
D	47 mm	Outside diameter
	h5	Tolerance
L	68 mm	Length
	h12	Tolerance
C _{min}	3.600 N	Load capacity dyn.
C _{0 min}	2.850 N	Load capacity stat.
C _{max}	3.800 N	Load capacity dyn.
C _{0 max}	3.600 N	Load capacity stat.
≈m	0,255 kg	Weight

Mounting dimensions

L ₂	51,7 mm	
	H13	Tolerance
B _{L2}	1,85 mm	
D _N	44,5 mm	
N ₂	2,5 mm	
	6	Number of rows balls