

**KB40-PP-AS**

Linear Ball Bearing

Linear ball bearings KB...-PP-AS, machined range, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

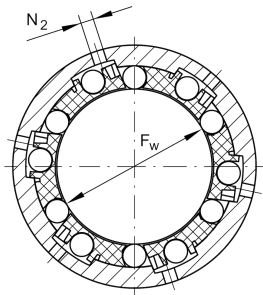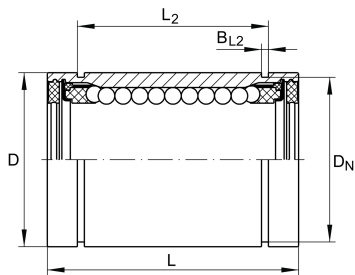

Your current product variant

Size code	40
-----------	----

Main Dimensions & Performance Data

F _w	40 mm	Bore diameter
	+0,013/-0,002	Tolerance
D	62 mm	Outside diameter
	h5	Tolerance
L	80 mm	Length
	h12	Tolerance
C _{min}	6.000 N	Load capacity dyn.
C _{0 min}	4.400 N	Load capacity stat.
C _{max}	6.400 N	Load capacity dyn.
C _{0 max}	5.600 N	Load capacity stat.
≈m	0,599 kg	Weight

Mounting dimensions

L ₂	60,3 mm	
	H13	Tolerance
B _{L2}	2,15 mm	
D _N	59 mm	
N ₂	3 mm	
	6	Number of rows balls