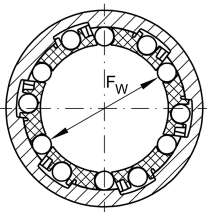
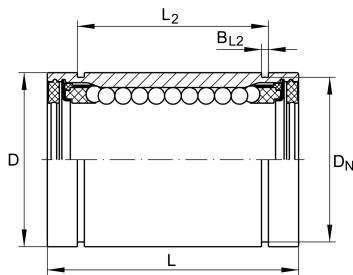
**KB50-PP** **Linear Ball Bearing**

Linear ball bearings KB...-PP, machined range, sealed on all sides, corrosion-resistant design possible

Technical information**Your current product variant**

Size code 50

Main Dimensions & Performance Data

F _w	50 mm	Bore diameter
	+0,013/-0,002	Tolerance
D	75 mm	Outside diameter
	h5	Tolerance
L	100 mm	Length
	h12	Tolerance
C _{min}	8.700 N	Load capacity dyn.
C _{0 min}	6.300 N	Load capacity stat.
C _{max}	9.200 N	Load capacity dyn.
C _{0 max}	8.000 N	Load capacity stat.
≈m	0,978 kg	Weight

Mounting dimensions

L ₂	77,3 mm	
	H13	Tolerance
B _{L2}	2,65 mm	
D _N	72 mm	
N ₂	4 mm	
	6	Number of rows balls