

**KB50-PP-AS**

Linear Ball Bearing

Linear ball bearings KB...-PP-AS, machined range, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

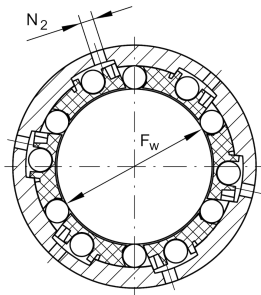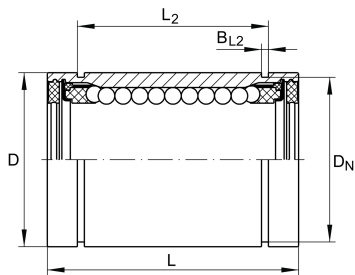

Your current product variant

Size code	50
-----------	----

Main Dimensions & Performance Data

F _W	50 mm	Bore diameter
	+0,013/-0,002	Tolerance
D	75 mm	Outside diameter
	h5	Tolerance
L	100 mm	Length
	h12	Tolerance
C _{min}	8.700 N	Load capacity dyn.
C _{0 min}	6.300 N	Load capacity stat.
C _{max}	9.200 N	Load capacity dyn.
C _{0 max}	8.000 N	Load capacity stat.
≈m	0,97 kg	Weight

Mounting dimensions

L ₂	77,3 mm	
	H13	Tolerance
B _{L2}	2,65 mm	
D _N	72 mm	
N ₂	4 mm	
	6	Number of rows balls