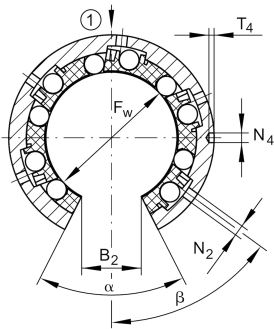
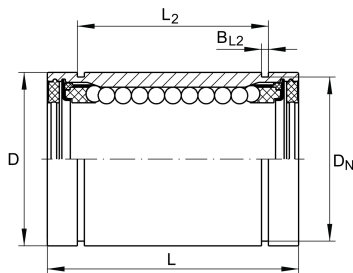
**KBO16-PP-AS** **Linear Ball Bearing**

Linear ball bearings KBO...-PP-AS, machined range, open design, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information**Your current product variant**

Size code	16	
Design	PP-AS	Sealed, relubrication facility

Main Dimensions & Performance Data

F _w	16 mm	Bore diameter
D	26 mm	Outside diameter
L	36 mm	Length
	h12	Tolerance
C _{max}	800 N	Load capacity dyn.
C _{0 max}	620 N	Load capacity stat.
≈m	37,36 g	Weight



Mounting dimensions

B ₂	10,1 mm	Width of sector opening
L ₂	24,6 mm	
	H13	Tolerance
B _{L2}	1,3 mm	
D _N	24,9 mm	
T ₄	1,2 mm	
N ₄	2,2 mm	
N ₂	2 mm	
α	78 °	Angle of sector opening
β	64 °	
	4	Number of rows balls