

**KBO40-PP**

Linear Ball Bearing

Linear ball bearings KBO...-PP, machined range, open design, sealed on all sides, corrosion-resistant design possible

Technical information

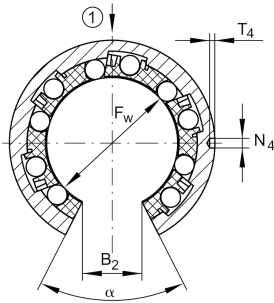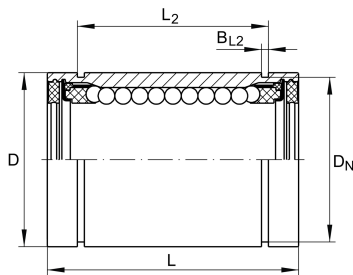

Your current product variant

Size code	40
-----------	----

Main Dimensions & Performance Data

F _W	40 mm	Bore diameter
D	62 mm	Outside diameter
L	80 mm	Length
	h12	Tolerance
C _{max}	6.100 N	Load capacity dyn.
C _{0 max}	4.600 N	Load capacity stat.
≈m	0,516 kg	Weight



Mounting dimensions

B ₂	18,2 mm	Width of sector opening
L ₂	60,3 mm	
	H13	Tolerance
B _{L2}	2,15 mm	
D _N	59 mm	
T ₄	1,5 mm	
N ₄	3 mm	
N ₂	3 mm	
α	54 °	Angle of sector opening
β	54 °	
	5	Number of rows balls