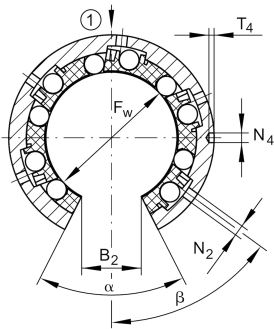
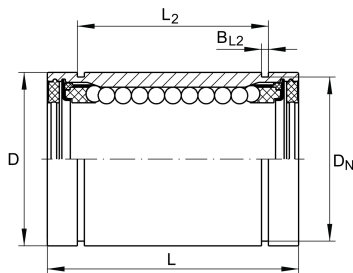
**KBO40-PP-AS** **Linear Ball Bearing**

Linear ball bearings KBO...-PP-AS, machined range, open design, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information**Your current product variant**

Size code	40	
Design	PP-AS	Sealed, relubrication facility

Main Dimensions & Performance Data

F _w	40 mm	Bore diameter
D	62 mm	Outside diameter
L	80 mm	Length
	h12	Tolerance
C _{max}	6.100 N	Load capacity dyn.
C _{0 max}	4.600 N	Load capacity stat.
≈m	511 g	Weight



Mounting dimensions

B 2	18,2 mm	Width of sector opening
L 2	60,3 mm	
	H13	Tolerance
B L2	2,15 mm	
D N	59 mm	
T 4	1,5 mm	
N 4	3 mm	
N 2	3 mm	
α	54 °	Angle of sector opening
β	54 °	
	5	Number of rows balls