

**KBS16-PP-AS**

Linear Ball Bearing

Linear ball bearings KBS..-PP-AS, machined range, adjustable, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

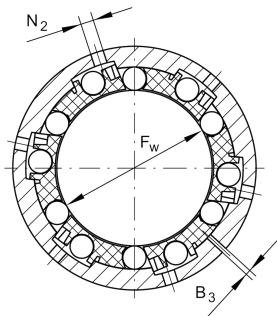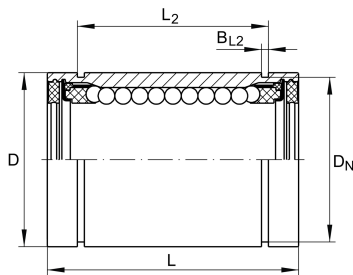

Your current product variant

Size code	16
-----------	----

Main Dimensions & Performance Data

F_w	16 mm	Bore diameter
D	26 mm	Outside diameter
L	36 mm	Length
	h12	Tolerance
C min	710 N	Load capacity dyn.
C 0 min	530 N	Load capacity stat.
C max	840 N	Load capacity dyn.
C 0 max	780 N	Load capacity stat.
≈m	42,25 g	Weight

Mounting dimensions

L_2	24,6 mm	
	H13	Tolerance
B_{L2}	1,3 mm	
B_3	1 mm	
D_N	24,9 mm	
N_2	2 mm	
α	54 °	
	5	Number of rows balls