

**KBS20-PP**

Linear Ball Bearing

Linear ball bearings KBS..-PP, machined range, adjustable, sealed on all sides, corrosion-resistant design possible

Technical information

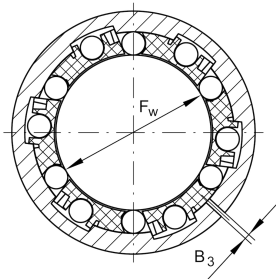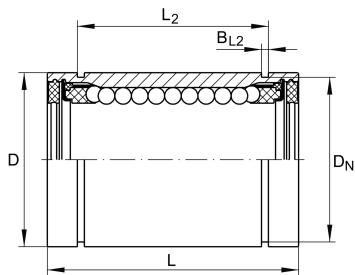

Your current product variant

Size code	20
-----------	----

Main Dimensions & Performance Data

F _w	20 mm	Bore diameter
D	32 mm	Outside diameter
L	45 mm	Length
	h12	Tolerance
C _{min}	1.570 N	Load capacity dyn.
C _{0 min}	1.230 N	Load capacity stat.
C _{max}	1.660 N	Load capacity dyn.
C _{0 max}	1.570 N	Load capacity stat.
≈m	87,02 g	Weight

Mounting dimensions

L ₂	31,2 mm	
	H13	Tolerance
B _{L2}	1,6 mm	
B ₃	1 mm	
D _N	30,3 mm	
N ₂	2 mm	
X	62,5 °	
	6	Number of rows balls