

**KBS20-PP-AS**

Linear Ball Bearing

Linear ball bearings KBS..-PP-AS, machined range, adjustable, sealed on all sides, with relubrication facility, corrosion-resistant design possible

Technical information

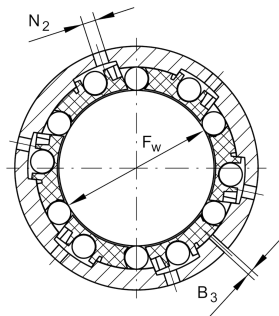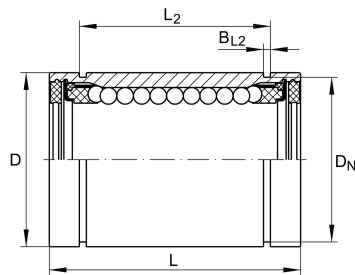

Your current product variant

Size code	20
-----------	----

Main Dimensions & Performance Data

F_w	20 mm	Bore diameter
D	32 mm	Outside diameter
L	45 mm	Length
	h12	Tolerance
C min	1.570 N	Load capacity dyn.
C 0 min	1.230 N	Load capacity stat.
C max	1.660 N	Load capacity dyn.
C 0 max	1.570 N	Load capacity stat.
≈m	87,74 g	Weight

Mounting dimensions

L_2	31,2 mm	
	H13	Tolerance
B_{L2}	1,6 mm	
B_3	1 mm	
D_N	30,3 mm	
N_2	2 mm	
α	62,5 °	
	6	Number of rows balls