

**KBS30-PP**

Linear Ball Bearing

Linear ball bearings KBS.-PP, machined range, adjustable, sealed on all sides, corrosion-resistant design possible

Technical information

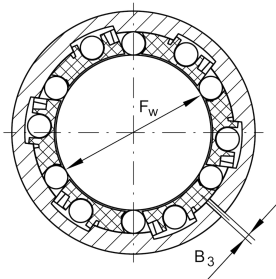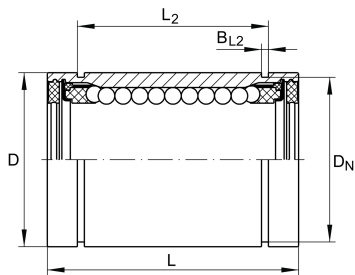

Your current product variant

Size code	30
-----------	----

Main Dimensions & Performance Data

F _w	30 mm	Bore diameter
D	47 mm	Outside diameter
L	68 mm	Length
	h12	Tolerance
C _{min}	3.600 N	Load capacity dyn.
C _{0 min}	2.850 N	Load capacity stat.
C _{max}	3.800 N	Load capacity dyn.
C _{0 max}	3.600 N	Load capacity stat.
≈m	0,297 kg	Weight

Mounting dimensions

L ₂	51,7 mm	
	H13	Tolerance
B _{L2}	1,85 mm	
B ₃	1 mm	
D _N	44,5 mm	
N ₂	2,5 mm	
X	64 °	
	6	Number of rows balls