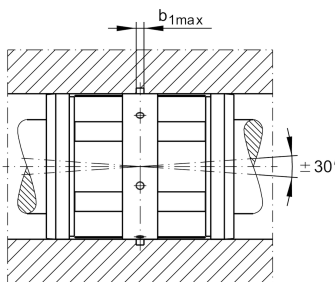
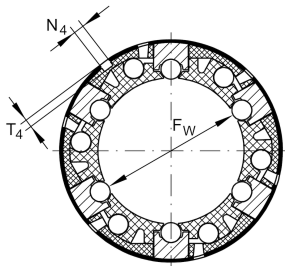
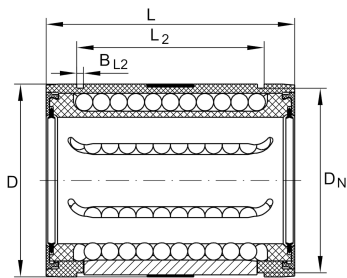
**KN30-B-PP** **Linear Ball Bearing**

Linear ball bearings KN...-B-PP, Lightweight range, closed design, sealed on all sides, with relubrication facility, adjustable angle

Technical information**Your current product variant**

Size code	30	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	30 mm	Bore diameter
D	47 mm	Outside diameter
L	68 mm	Length
C_{min}	3.750 N	Load capacity dyn.
$C_{0 min}$	2.850 N	Load capacity stat.
C_{max}	3.950 N	Load capacity dyn.
$C_{0 max}$	3.650 N	Load capacity stat.
$\approx m$	0,193 kg	Weight

Mounting dimensions

L_2	51,7 mm
B_{L2}	1,85 mm
D_N	44,7 mm
T_4	2,2 mm
N_4	3 mm
$b_{1 max}$	2,5 mm