
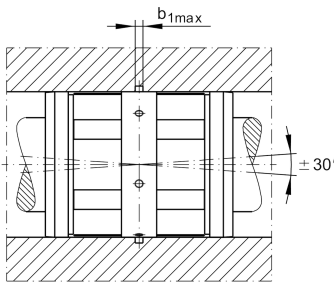
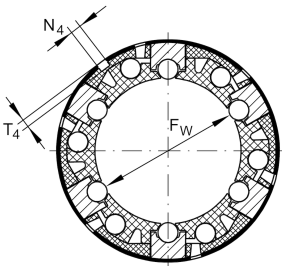


KN40-B-PP

Linear Ball Bearing

Linear ball bearings KN...-B-PP, Lightweight range, closed design, sealed on all sides, with relubrication facility, adjustable angle

Technical information

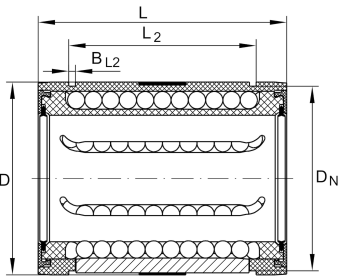

Your current product variant

Size code	40	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _w	40 mm	Bore diameter
D	62 mm	Outside diameter
L	80 mm	Length
C _{min}	6.300 N	Load capacity dyn.
C _{0 min}	4.350 N	Load capacity stat.
C _{max}	6.700 N	Load capacity dyn.
C _{0 max}	5.600 N	Load capacity stat.
≈m	0,374 kg	Weight

Mounting dimensions

L ₂	60,3 mm
B _{L2}	2,15 mm
D _N	59,4 mm
T ₄	2,2 mm
N ₄	3 mm
b _{1 max}	3 mm