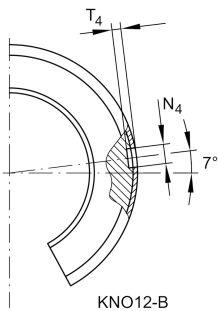
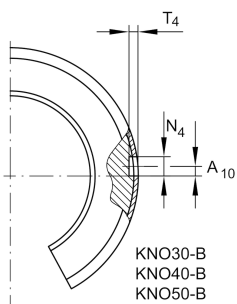
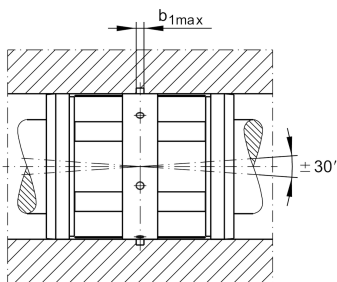
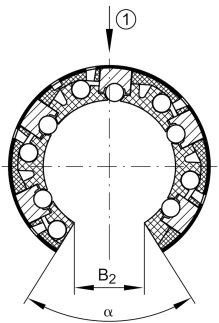
**KNO12-B-PP** **Linear Ball Bearing**

Linear ball bearings KNO...-B-PP, Lightweight range, open design, sealed on all sides, with relubrication facility, adjustable angle

Technical information

KNO12-B

KNO30-B
KNO40-B
KNO50-B**Your current product variant**

Size code	12	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _W	12 mm	Bore diameter
D	22 mm	Outside diameter
L	32 mm	Length
C _{max}	840 N	Load capacity dyn.
C _{0 max}	640 N	Load capacity stat.
≈m	20 g	Weight

Mounting dimensions

B 2	6,5 mm	Width of sector opening
T 4	0,7 mm	
N 4	3 mm	
α	66 °	Angle of sector opening
b 1 max	1,5 mm	
	4	Number of rows balls