



**KNO16-B-PP** **Linear Ball Bearing**

Linear ball bearings KNO...-B-PP, Lightweight range, open design, sealed on all sides, with relubrication facility, adjustable angle

**Technical information**

KNO16-B  
KNO20-B

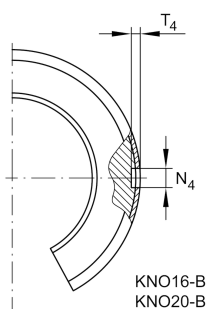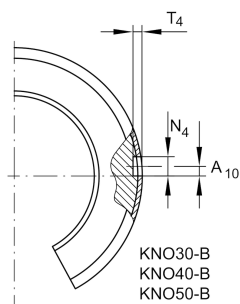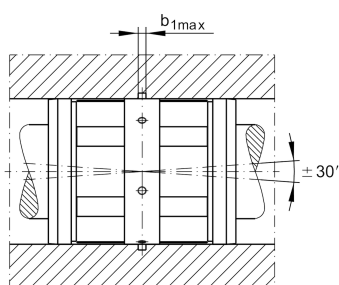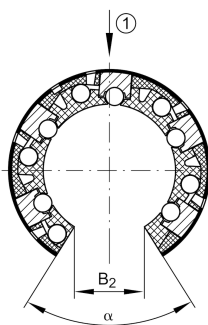

KNO30-B  
KNO40-B  
KNO50-B

**Your current product variant**

|           |    |        |
|-----------|----|--------|
| Size code | 16 |        |
| Seal      | PP | Sealed |

**Main Dimensions & Performance Data**

|             |         |                     |
|-------------|---------|---------------------|
| $F_W$       | 16 mm   | Bore diameter       |
| D           | 26 mm   | Outside diameter    |
| L           | 36 mm   | Length              |
| $C_{max}$   | 1.000 N | Load capacity dyn.  |
| $C_{0 max}$ | 750 N   | Load capacity stat. |
| $\approx m$ | 20 g    | Weight              |

**Mounting dimensions**

|         |        |                         |
|---------|--------|-------------------------|
| B 2     | 9 mm   | Width of sector opening |
| T 4     | 0,7 mm |                         |
| N 4     | 3 mm   |                         |
| α       | 68 °   | Angle of sector opening |
| b 1 max | 1,5 mm |                         |
|         | 4      | Number of rows balls    |