



**KNO20-B-PP**

## Linear Ball Bearing

Linear ball bearings KNO...-B-PP, Lightweight range, open design, sealed on all sides, with relubrication facility, adjustable angle

## Technical information

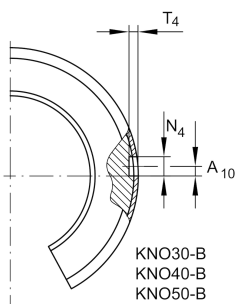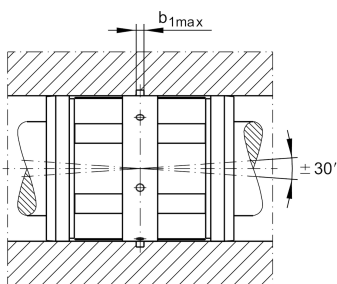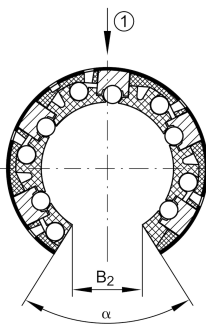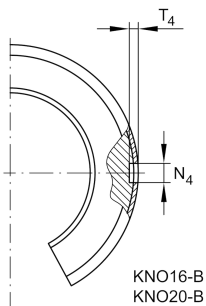

## Your current product variant

|           |    |        |
|-----------|----|--------|
| Size code | 20 |        |
| Seal      | PP | Sealed |

## Main Dimensions &amp; Performance Data

|                    |         |                     |
|--------------------|---------|---------------------|
| F <sub>W</sub>     | 20 mm   | Bore diameter       |
| D                  | 32 mm   | Outside diameter    |
| L                  | 45 mm   | Length              |
| C <sub>max</sub>   | 1.740 N | Load capacity dyn.  |
| C <sub>0 max</sub> | 1.240 N | Load capacity stat. |
| ≈m                 | 50 g    | Weight              |

## Mounting dimensions

|         |        |                         |
|---------|--------|-------------------------|
| B 2     | 9 mm   | Width of sector opening |
| T 4     | 0,9 mm |                         |
| N 4     | 3 mm   |                         |
| α       | 55 °   | Angle of sector opening |
| b 1 max | 2,5 mm |                         |
|         | 5      | Number of rows balls    |