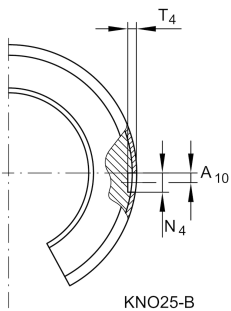
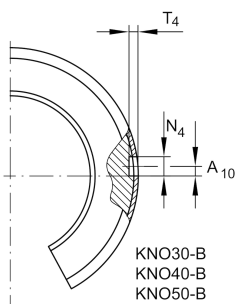
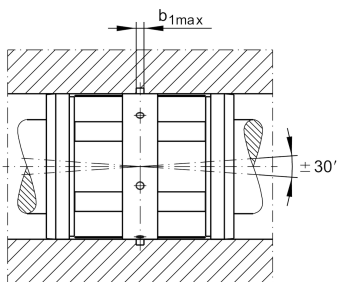
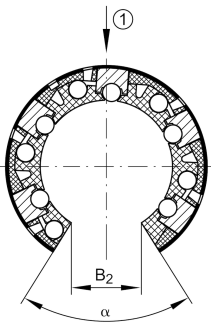
**KNO25-B-PP** **Linear Ball Bearing**

Linear ball bearings KNO...-B-PP, Lightweight range, open design, sealed on all sides, with relubrication facility, adjustable angle

Technical information

KNO25-B

KNO30-B
KNO40-B
KNO50-B**Your current product variant**

Size code	25	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_W	25 mm	Bore diameter
D	40 mm	Outside diameter
L	58 mm	Length
C_{max}	3.100 N	Load capacity dyn.
$C_{0 max}$	2.260 N	Load capacity stat.
$\approx m$	0,113 kg	Weight

Mounting dimensions

B_2	11,5 mm	Width of sector opening
T_4	1,4 mm	
A_{10}	1,5 mm	Angle of sector opening
N_4	3 mm	
α	57 °	Angle of sector opening
$b_{1 max}$	2,5 mm	
	5	Number of rows balls