
**KS12-PP**



Linear Ball Bearing

Linear ball bearings KS...-PP, heavy load range, lip seals on both sides


Technical information

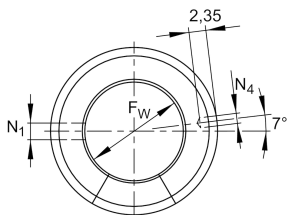

KS12
KSO12

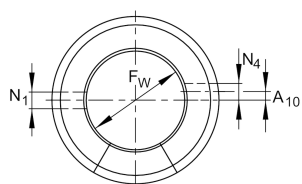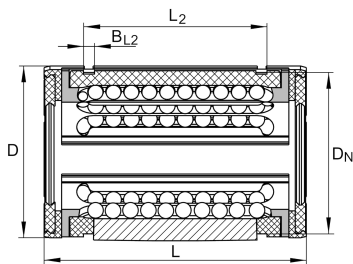

KS30, 40, 50
KSO30, 40, 50

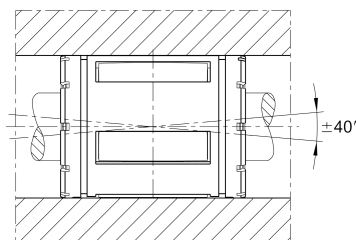

Your current product variant

Size code	12	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	12 mm	Bore diameter
D	22 mm	Outside diameter
L	32 mm	Length
C_{min}	630 N	Load capacity dyn.
$C_{0 min}$	600 N	Load capacity stat.
C_{max}	900 N	Load capacity dyn.
$C_{0 max}$	1.100 N	Load capacity stat.
$\approx m$	0,02 kg	Weight

Mounting dimensions

L_2	22,6 mm
H13	Tolerance
B_{L2}	1,3 mm
D_N	21 mm
N_4	3 mm
8	Number of rows balls