
**KS16-PP**



Linear Ball Bearing

Linear ball bearings KS...-PP, heavy load range, lip seals on both sides


Technical information

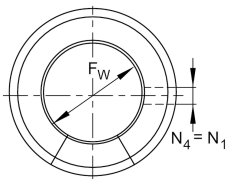

KS16, 20
KSO16, 20

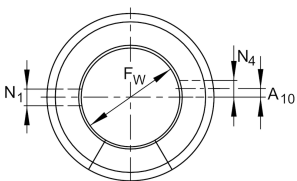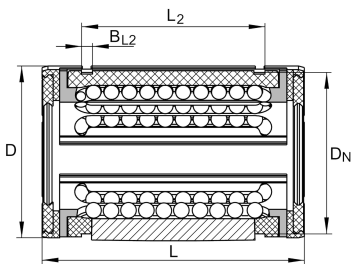

KS30, 40, 50
KSO30, 40, 50

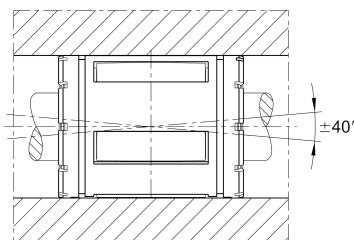

Your current product variant

Size code	16	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	16 mm	Bore diameter
D	26 mm	Outside diameter
L	36 mm	Length
C_{min}	1.060 N	Load capacity dyn.
$C_{0 min}$	950 N	Load capacity stat.
C_{max}	1.430 N	Load capacity dyn.
$C_{0 max}$	1.550 N	Load capacity stat.
$\approx m$	0,03 kg	Weight

Mounting dimensions

L_2	24,6 mm
H13	Tolerance
B_{L2}	1,3 mm
D_N	25 mm
N_1	3 mm
N_4	3 mm

8

Number of rows balls