


**KS25-PP** **Linear Ball Bearing**


Linear ball bearings KS...-PP, heavy load range, lip seals on both sides

Technical information

KS25
KSO25

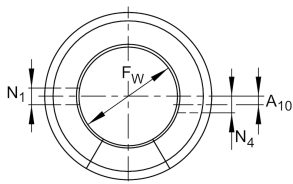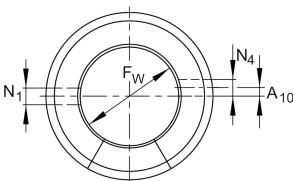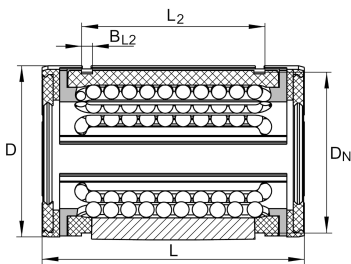

KS30, 40, 50
KSO30, 40, 50

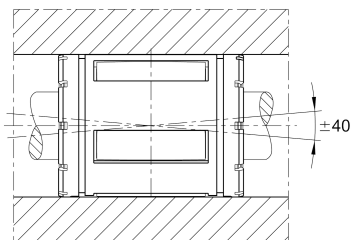**Your current product variant**

Size code	25	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	25 mm	Bore diameter
D	40 mm	Outside diameter
L	58 mm	Length
C_{min}	2.700 N	Load capacity dyn.
$C_{0 min}$	2.430 N	Load capacity stat.
C_{max}	3.950 N	Load capacity dyn.
$C_{0 max}$	4.300 N	Load capacity stat.
$\approx m$	0,1 kg	Weight

Mounting dimensions

L_2	43,7 mm	
H13		Tolerance
B_{L2}	1,85 mm	
D_N	38 mm	
A_{10}	1,5 mm	Angle of sector opening
N_1	3,5 mm	
N_4	3 mm	
8		Number of rows balls