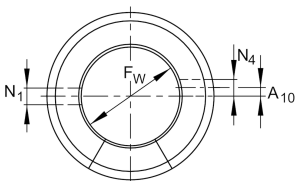
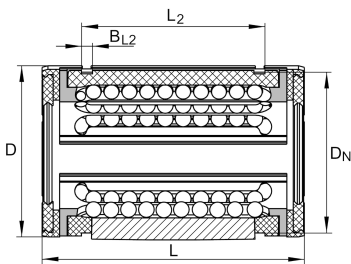
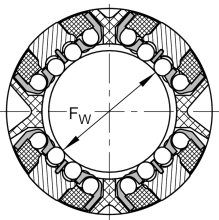
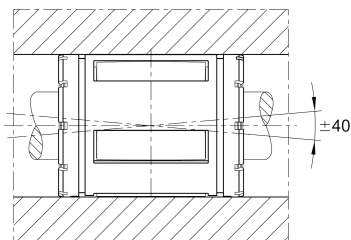
**KS30-PP** **Linear Ball Bearing**

Linear ball bearings KS...-PP, heavy load range, lip seals on both sides

Technical information

KS30, 40, 50
KSO30, 40, 50

**Your current product variant**

Size code	30	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _w	30 mm	Bore diameter
D	47 mm	Outside diameter
L	68 mm	Length
C _{min}	4.650 N	Load capacity dyn.
C _{0 min}	3.970 N	Load capacity stat.
C _{max}	5.900 N	Load capacity dyn.
C _{0 max}	6.000 N	Load capacity stat.
≈m	0,18 kg	Weight

Mounting dimensions

L ₂	51,7 mm	
H13		Tolerance
B _{L2}	1,85 mm	
D _N	44,7 mm	
A ₁₀	2 mm	Angle of sector opening
N ₁	3,5 mm	
N ₄	3 mm	
8		Number of rows balls