


**KS40-PP**


Linear Ball Bearing

Linear ball bearings KS...-PP, heavy load range, lip seals on both sides

Technical information

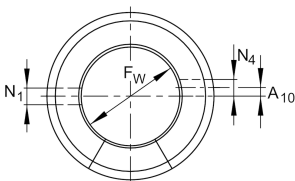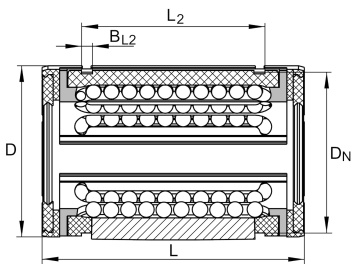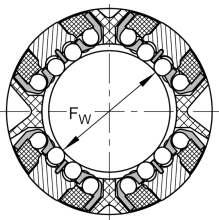

KS30, 40, 50
KSO30, 40, 50

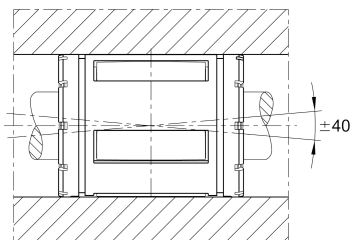

Your current product variant

Size code	40	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _w	40 mm	Bore diameter
D	62 mm	Outside diameter
L	80 mm	Length
C _{min}	8.800 N	Load capacity dyn.
C _{0 min}	7.200 N	Load capacity stat.
C _{max}	10.200 N	Load capacity dyn.
C _{0 max}	9.600 N	Load capacity stat.
≈m	0,345 kg	Weight

Mounting dimensions

L ₂	60,3 mm	
H13		Tolerance
B _{L2}	2,15 mm	
D _N	59,4 mm	
A ₁₀	1,5 mm	Angle of sector opening
N ₁	3,5 mm	
N ₄	3 mm	
8		Number of rows balls