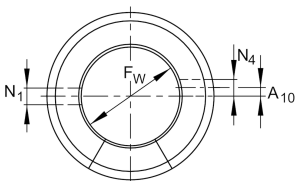
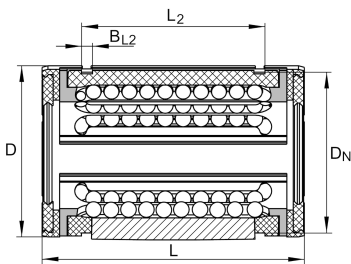
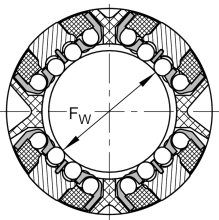
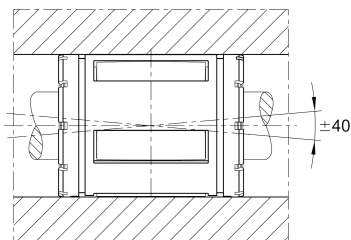
**KS50-PP** **Linear Ball Bearing**

Linear ball bearings KS...-PP, heavy load range, lip seals on both sides

Technical information

KS30, 40, 50
KSO30, 40, 50

**Your current product variant**

Size code	50	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _w	50 mm	Bore diameter
D	75 mm	Outside diameter
L	100 mm	Length
C _{min}	12.300 N	Load capacity dyn.
C _{0 min}	9.700 N	Load capacity stat.
C _{max}	15.100 N	Load capacity dyn.
C _{0 max}	13.900 N	Load capacity stat.
≈m	0,61 kg	Weight

Mounting dimensions

L ₂	77,3 mm	
H13		Tolerance
B _{L2}	2,65 mm	
D _N	71,4 mm	
A ₁₀	2,5 mm	Angle of sector opening
N ₁	4,5 mm	
N ₄	5 mm	
8		Number of rows balls