
**KSO12-PP**



Linear Ball Bearing

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information

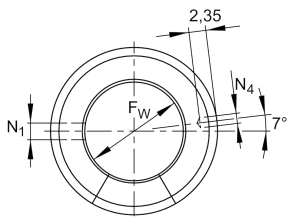

KS12
KSO12

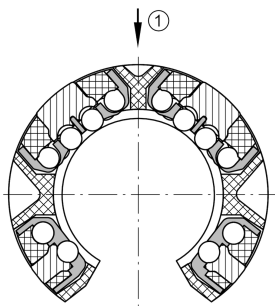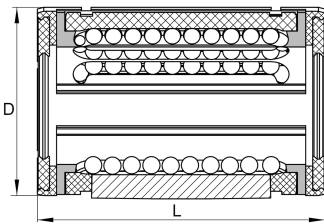

KS30, 40, 50
KSO30, 40, 50

Your current product variant

Size code	12	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	12 mm	Bore diameter
D	22 mm	Outside diameter
L	32 mm	Length
C_{max}	900 N	Load capacity dyn.
$C_{0 max}$	1.100 N	Load capacity stat.
m	0,014 kg	Weight

Mounting dimensions

B 2	7,6 mm	Width of sector opening
N 1	3 mm	
N 4	3 mm	
α	78 °	Angle of sector opening
	6	Number of rows balls



View product details on medias

05.08.2026, 14:41:41 UTC

SCHAEFFLER

