
**KSO16-PP**




Linear Ball Bearing

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information

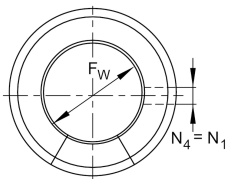

KS16, 20
KSO16, 20

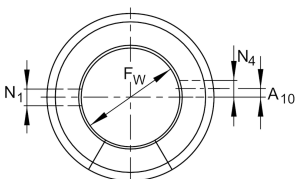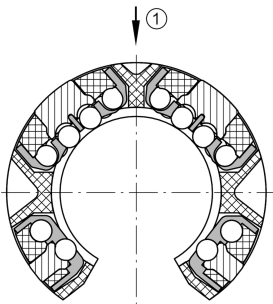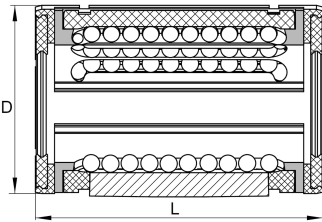

KS30, 40, 50
KSO30, 40, 50

Your current product variant

Size code	16	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	16 mm	Bore diameter
D	26 mm	Outside diameter
L	36 mm	Length
C_{max}	1.430 N	Load capacity dyn.
$C_{0 max}$	1.550 N	Load capacity stat.
m	21,39 g	Weight

Mounting dimensions

B 2	10,1 mm	Width of sector opening
N 1	3 mm	
N 4	3 mm	
α	78 °	Angle of sector opening
	6	Number of rows balls



View product details on medias

06.09.2026, 02:08:35 UTC

SCHAEFFLER

