



**KSO30-PP**

Linear Ball Bearing

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information

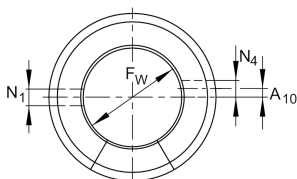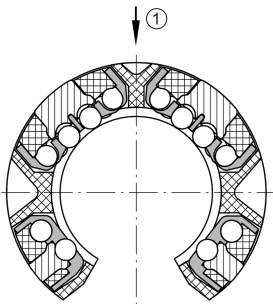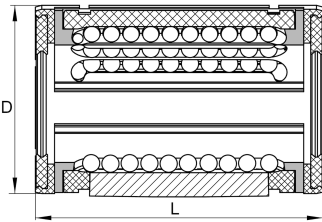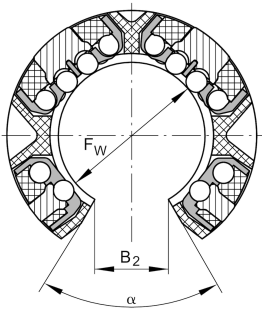

KS30, 40, 50
KSO30, 40, 50

Your current product variant

Size code	30	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	30 mm	Bore diameter
D	47 mm	Outside diameter
L	68 mm	Length
C_{max}	5.900 N	Load capacity dyn.
$C_{0 max}$	6.000 N	Load capacity stat.
m	0,14 kg	Weight

Mounting dimensions

B 2	14,3 mm	Width of sector opening
A 10	2 mm	Angle of sector opening
N 1	3,5 mm	
N 4	3 mm	
α	57 °	Angle of sector opening
	6	Number of rows balls



View product details on medias

06.09.2026, 02:08:31 UTC

SCHAEFFLER

