



**KSO40-PP**

Linear Ball Bearing

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information

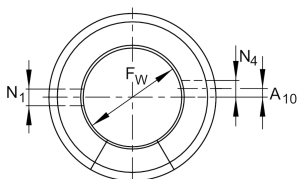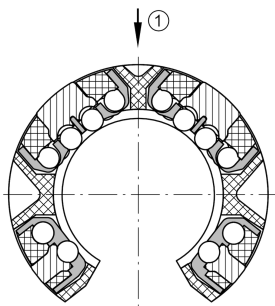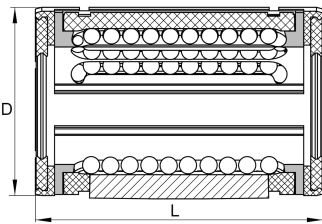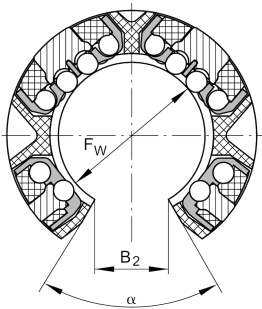

KS30, 40, 50
KSO30, 40, 50

Your current product variant

Size code	40	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	40 mm	Bore diameter
D	62 mm	Outside diameter
L	80 mm	Length
C_{max}	10.200 N	Load capacity dyn.
$C_{0 max}$	9.600 N	Load capacity stat.
m	0,27 kg	Weight

Mounting dimensions

B 2	18,2 mm	Width of sector opening
A 10	1,5 mm	Angle of sector opening
N 1	3,5 mm	
N 4	3 mm	
α	54 °	Angle of sector opening
	6	Number of rows balls



View product details on medias

06.09.2026, 02:08:45 UTC

SCHAEFFLER

