
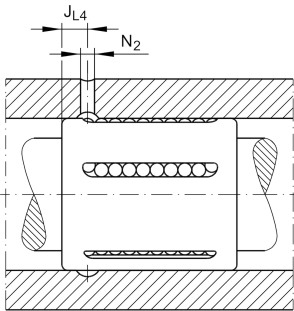


KH06-PP

Linear Ball Bearing

Linear ball bearings with initial greasing,
sealed on both sides, with relubrication facility

Technical information

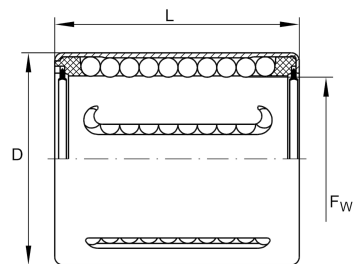

Your current product variant

Size code	06	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _w	6 mm	Diameter shaft
D	12 mm	Outer diameter
L	22 mm	Length
C _{min}	340 N	Load capacity dyn.
C _{0 min}	240 N	Load capacity stat.
C _{max}	390 N	Load capacity dyn.
C _{0 max}	340 N	Load capacity stat.
≈m	7,3 g	Weight

Mounting dimensions

J _{L4}	4 mm
N ₂	2 mm