
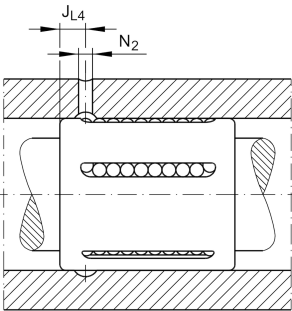


KH30-PP

Linear Ball Bearing

Linear ball bearings with initial greasing,
sealed on both sides, with relubrication facility

Technical information

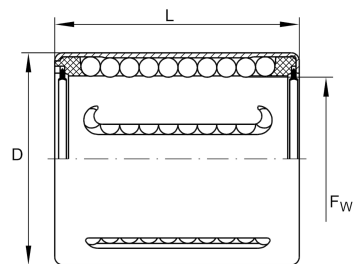

Your current product variant

Size code	30	
Seal	PP	Sealed

Main Dimensions & Performance Data

F _w	30 mm	Diameter shaft
D	40 mm	Outer diameter
L	50 mm	Length
C _{min}	3.300 N	Load capacity dyn.
C _{0 min}	2.700 N	Load capacity stat.
C _{max}	3.300 N	Load capacity dyn.
C _{0 max}	3.100 N	Load capacity stat.
≈m	94,7 g	Weight

Mounting dimensions

J _{L4}	8 mm
N ₂	2,5 mm