
**LFR50/8-6-2Z**

Yoke type track roller

Yoke type track roller

Technical information

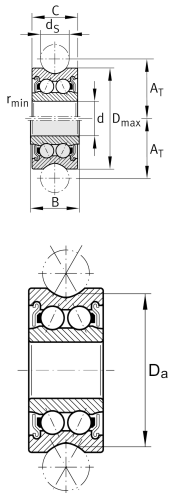

Your current product variant

Size code	50/8	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	8 mm	
D _{max}	24 mm	
B	11 mm	Width, inner ring
≈m	0,025 kg	Weight

Mounting dimensions

A _T	14 mm	
C	11 mm	
D _a	22,8 mm	Diameter of rolling
d _s	6 mm	
r _{min}	0,3 mm	

Main dimensions

C _{r w}	4.100 N	Effective dynamic load rating as track roller (radial)
C _{0r w}	2.300 N	Effective static load rating as track roller (radial)
C _{ur w}	115 N	Limit of fatigue load
F _{r per}	2.550 N	Permissible dynamic limit load
F _{0r per}	4.600 N	Permissible static limit load



Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------