

**LFR5201-10-2RS-RB**

Yoke type track roller

Yoke type track roller

Technical information

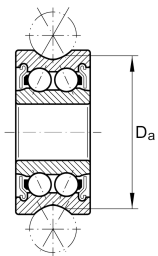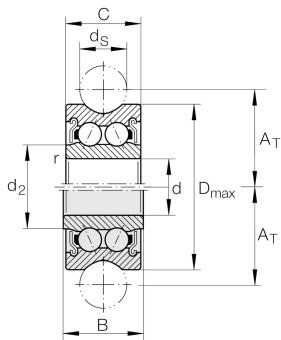

Your current product variant

Size code	5201	
Seal	2RS	Double-sided sliding seal
Material	RB	Corrosion-resistant design

Main Dimensions & Performance Data

d	12 mm	
D _{max}	35 mm	
B	15,9 mm	Width, inner ring
≈m	71 g	Weight

Mounting dimensions

A _T	20,63 mm	
C	15,9 mm	
D _a	32,25 mm	Diameter of rolling
d _s	10 mm	
r _{min}	0,6 mm	

Main dimensions

C _{rw}	8.400 N	Effective dynamic load rating as track roller (radial)
C _{0rw}	5.000 N	Effective static load rating as track roller (radial)
C _{urw}	250 N	Limit of fatigue load
F _{r per}	4.750 N	Permissible dynamic limit load
F _{0r per}	10.000 N	Permissible static limit load



Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------