
**LFR5204-16-2Z**

Yoke type track roller

Yoke type track roller

Technical information

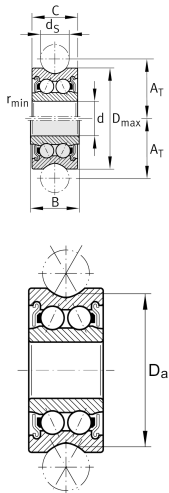

Your current product variant

Size code	5204	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	20 mm	
D _{max}	52 mm	
B	22,6 mm	Width, inner ring
≈m	0,177 kg	Weight

Mounting dimensions

A _T	31,5 mm	
C	20,6 mm	
D _a	49,14 mm	Diameter of rolling
d _s	16 mm	
r _{min}	1 mm	

Main dimensions

C _{r w}	15.300 N	Effective dynamic load rating as track roller (radial)
C _{0r w}	10.100 N	Effective static load rating as track roller (radial)
C _{ur w}	520 N	Limit of fatigue load
F _{r per}	10.500 N	Permissible dynamic limit load
F _{0r per}	20.200 N	Permissible static limit load



Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------