
**LFR5206-20-2Z**

Yoke type track roller

Yoke type track roller

Technical information

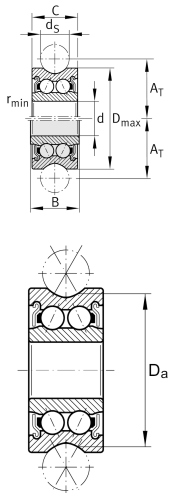

Your current product variant

Size code	5206	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	25 mm	
D _{max}	72 mm	
B	25,8 mm	Width, inner ring
≈m	0,43 kg	Weight

Mounting dimensions

A _T	41 mm	
C	23,8 mm	
D _a	64,68 mm	Diameter of rolling
d _s	20 mm	
r _{min}	1 mm	

Main dimensions

C _{r w}	23.100 N	Effective dynamic load rating as track roller (radial)
C _{0r w}	16.400 N	Effective static load rating as track roller (radial)
C _{ur w}	870 N	Limit of fatigue load
F _{r per}	21.100 N	Permissible dynamic limit load
F _{0r per}	33.000 N	Permissible static limit load



Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------