
**LFR5208-40-2Z**

Yoke type track roller

Yoke type track roller

Technical information

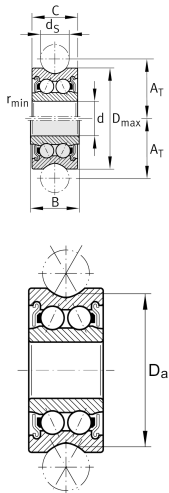

Your current product variant

Size code	5208	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	40 mm	
D _{max}	98 mm	
B	38 mm	Width, inner ring
≈m	1,009 kg	Weight

Mounting dimensions

A _T	62,5 mm	
C	36 mm	
D _a	90,36 mm	Diameter of rolling
d _s	40 mm	
r _{min}	1,1 mm	

Main dimensions

C _{r w}	38.500 N	Effective dynamic load rating as track roller (radial)
C _{0r w}	29.000 N	Effective static load rating as track roller (radial)
C _{ur w}	1.480 N	Limit of fatigue load
F _{r per}	51.000 N	Permissible dynamic limit load
F _{0r per}	58.000 N	Permissible static limit load



Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------