
**LFR5301-10-2Z**

Yoke type track roller

Yoke type track roller

Technical information

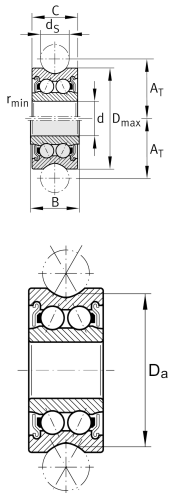

Your current product variant

Size code	5301	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	12 mm	
D _{max}	42 mm	
B	19 mm	Width, inner ring
≈m	137 g	Weight

Mounting dimensions

A _T	24 mm	
C	19 mm	
D _a	38,95 mm	Diameter of rolling
d _s	10 mm	
r _{min}	0,6 mm	

Main dimensions

C _{rw}	13.200 N	Effective dynamic load rating as track roller (radial)
C _{0rw}	7.700 N	Effective static load rating as track roller (radial)
C _{urw}	370 N	Limit of fatigue load
F _{rper}	6.400 N	Permissible dynamic limit load
F _{0rper}	15.400 N	Permissible static limit load



Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------