
**LFR5302-10-2Z**

Yoke type track roller

Yoke type track roller

Technical information

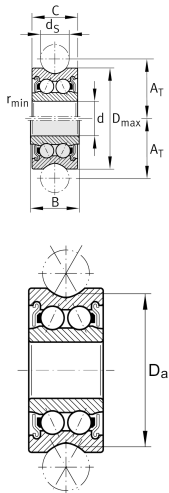

Your current product variant

Size code	5302	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	15 mm	
D _{max}	47 mm	
B	19 mm	Width, inner ring
≈m	0,171 kg	Weight

Mounting dimensions

A _T	26,63 mm	
C	19 mm	
D _a	44,25 mm	Diameter of rolling
d _s	10 mm	
r _{min}	1 mm	

Main dimensions

C _{rw}	14.500 N	Effective dynamic load rating as track roller (radial)
C _{0rw}	9.100 N	Effective static load rating as track roller (radial)
C _{urw}	455 N	Limit of fatigue load
F _{rper}	9.400 N	Permissible dynamic limit load
F _{0rper}	18.200 N	Permissible static limit load



View product details on medias

07.08.2026, 02:19:47 UTC

SCHAEFFLER

Additional information

LFE/LFZ	siehe Katalog: LF1	Possible roller-pin combination
---------	--------------------	---------------------------------