

**LFRI50/8-6-2Z**

Yoke type track roller

Yoke type track roller

Technical information

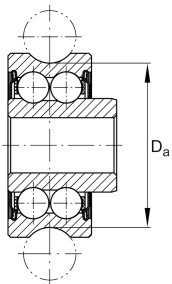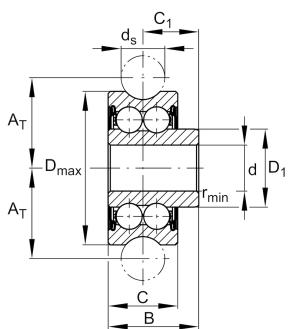

Your current product variant

Size code	50/8	
Seal	2Z	Gap seal on both sides

Main Dimensions & Performance Data

d	6,1 mm	
D max	24 mm	
B	15,1 mm	Width, inner ring
≈m	25 g	Weight

Mounting dimensions

A _T	14 mm	
C	11 mm	
C ₁	9,6 mm	
D ₁	12,6 mm	
D _{1 Tol}	j6	
D _a	22,8 mm	Diameter of rolling
d _s	6 mm	
r _{min}	0,5 mm	



Main dimensions

C _{r w}	4.100 N	Effective dynamic load rating as track roller (radial)
C _{0r w}	2.300 N	Effective static load rating as track roller (radial)
C _{ur}	115 N	Limit of fatigue load
F _{r per}	2.550 N	Permissible dynamic limit load
F _{0r per}	4.600 N	Permissible static limit load