
**LFR2202-10-2RSR-NA**

Yoke type track roller

Yoke type track roller

Technical information

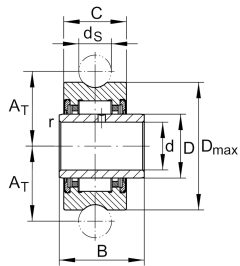

Your current product variant

Size code	2202	
Seal	2RSR	double-sided sliding seal
Code	NA	With inner ring
Inner ring	IR15X20X16	

Main Dimensions & Performance Data

d	15 mm	
D _{max}	35 mm	
B	16 mm	Width, inner ring
B _{Tol}	0 mm	
B _{Tol}	- 0,12 mm	
≈m	67,71 g	Weight

Mounting dimensions

A _T	20,63 mm
C	13,8 mm
D	20 mm
ds	10 mm
r _{min}	0,3 mm



Main dimensions

C _{r w}	6.500 N	Effective dynamic load rating as track roller (radial)
C _{0r w}	9.300 N	Effective static load rating as track roller (radial)
C _{ur w}	1.310 N	Limit of fatigue load