
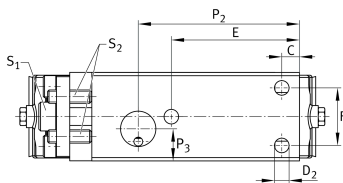
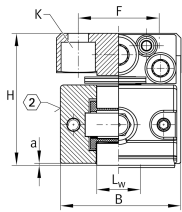


RUSV42126-KS

Linear recirculating roller bearing unit

Linear roller bearings, with spacer elements,
with integrated adjusting gib, RUSV...-KS

Technical information

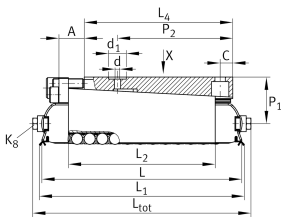


Your current product variant

Size code	42126	
Suffix code	KS	With end face lubrication connectors

Main Dimensions & Performance Data

L	138 mm	Length total
B	40 mm	Width
H	42 mm	Height
C	122.000 N	Basic dynamic load capacity
C ₀	209.000 N	Basic static load capacity
m	1,33 kg	Weight

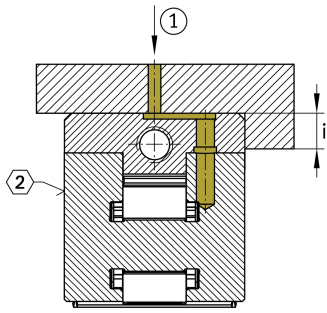

Mounting dimensions

L	126 mm	
L ₁	132 mm	
L ₃	92,4 mm	
L ₄	94 mm	
a	0,3 mm	
L _w	14 mm	
C	8 mm	
E	58 mm	Mounting dimension
F	26 mm	
i	6 mm	Mounting dimension
P ₁	29,5 mm	
d ₁	16 mm	
P ₂	73 mm	
P ₃	14,5 mm	
d	3 mm	
K	M6	Lubrication connector DIN3405-A
S ₁	6 mm	Hexagon socket adjusting screw
S ₂	3 mm	Hexagon socket counter forcing screw
K	M6	Size thread k DIN
K M _A	17 Nm	Tightening torque fixing screws
D ₂	6,6 mm	
A _{max}	10 mm	Screw stroke A
Delta h _{max}	0,52 mm	Adjustment maximum
	0,05 mm	Adjustment screw revolution



Related products

UG9741, UGN9741-A, UZ9741, UZN9741-A, UFK4710, UFB6412	Suitable Guide Rails
--	----------------------