




GWN12-B

Shaft block

Shaft block

Technical information

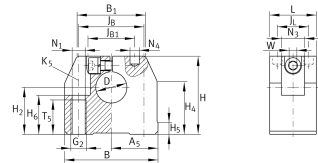

Your current product variant

Size code	12
Version	B

Main Dimensions & Performance Data

D	12 mm	Diameter
Tol D	H8	Tolerance
B	43 mm	Width
L	20 mm	Length
H	35 mm	Height
≈m	60 g	Weight

**Mounting dimensions**

J _B	30 mm	Mounting Dimension
Tol J _B	+ 0,15 mm	Upper tolerance
Tol J _B	- 0,15 mm	Lower tolerance
J _{B1}	20 mm	Mounting Dimension
B ₁	34 mm	Mounting Dimension
A ₅	21,5 mm	Mounting Dimension
Tol A ₅	- 0,01 mm	Lower tolerance
Tol A ₅	+ 0,01 mm	Upper tolerance
J _L	13 mm	Mounting Dimension
H ₂	20 mm	Mounting Dimension
Tol H ₂	+ 0,01 mm	Upper tolerance
Tol H ₂	- 0,01 mm	Lower tolerance
H ₄	26,6 mm	Mounting Dimension
H ₅	5,4 mm	Mounting Dimension
T ₅	13 mm	Mounting Dimension
H ₆	16,5 mm	Mounting Dimension
G ₂	M6	Mounting thread below
N ₁	5,3 mm	Mounting Dimension
N ₃	10 mm	Mounting Dimension
N ₄	4 mm	Mounting Dimension
K ₅	M5	Size thread fixing screws above
W	3 mm	Width across Flat