


GWH30-B

Shaft block

Shaft block

Technical information

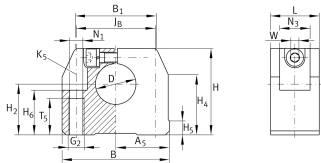

Your current product variant

Size code	30	
Suffix code	B	Version

Main Dimensions & Performance Data

D	30 mm	Diameter
Tol D	H8	Tolerance
B	67 mm	Width across flats
L	30 mm	Length
H	60 mm	Heigth
≈m	0,22 kg	Weight



Mounting dimensions

J _B	49 mm	Mounting Dimension
Tol J _B	+ 0,15 mm	Upper tolerance
Tol J _B	- 0,15 mm	Lower tolerance
A ₅	33,5 mm	Mounting Dimension
B ₁	49,5 mm	Mounting Dimension
H ₂	34 mm	Mounting Dimension
Tol H ₂	+ 0,1 mm	Upper tolerance
Tol H ₂	- 0,1 mm	Lower tolerance
H ₄	42,7 mm	Mounting Dimension
H ₅	8 mm	Mounting Dimension
T ₅	22 mm	Mounting Dimension
H ₆	29 mm	Mounting Dimension
G ₂	M10	Mounting thread below
N ₁	8,4 mm	Mounting Dimension
N ₃	18 mm	Mounting Dimension
K ₅	M8	Sie thread fixing screws above
W	5 mm	Width across Flat