


KFB30-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; with flange, sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

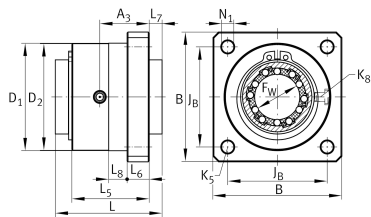

Your current product variant

Size code	30
Seal	PP
Relubrication	AS

Technical data

	6	Ball rows
≈m	0,62 kg	Weight

Main Dimensions & Performance Data

F _W	30 mm	Diameter of ball complement
Tol F _W	+ 0,011 mm	Upper tolerance
Tol F _W	- 0,001 mm	Lower tolerance
L	68 mm	Length
B	80 mm	Width
C	3.600 N	Load capacity dyn. C
C ₀	2.850 N	Load capacity stat. C ₀



Mounting dimensions

L 5	50 mm	
L 6	14 mm	Thickness
L 7	8 mm	
A 3	26 mm	
N 1	9 mm	Diameter
K 5	M8	
D 1	65,5 mm	Diameter
Tol D 1	+ 0,2 mm	Upper tolerance
D 2	66 mm	Diameter
Tol D 2	g7	Upper tolerance
J B	60 mm	
L 8	10 mm	
K 8	NIPA1	Lubrication nipple