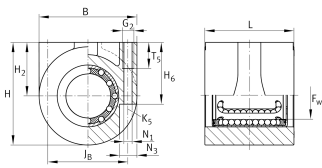
**KGHA20-PP** [🔗](#)**Linear Ball Bearing and Housing Unit**

Linear Ball Bearing and Housing Units,
Sealed, Greased, Corrosion-resistant Design
Possible

Technical information**Your current product variant**

Size code	20	
Seal	PP	Sealed

Main Dimensions & Performance Data

H	48,5 mm	Height
B	47 mm	Width
L	39 mm	Length
	+ 0,5 mm	Tolerance
C	1.110 N	Dynamic load rating
C ₀	790 N	Static load rating
m	0,303 kg	Weight

Mounting dimensions

H ₆	29 mm	
T ₅	15 mm	
J _B	38 mm	
Tol J _B	± 0,1 mm	Tolerance
G ₂	M6	
N ₁	5,1 mm	
N ₃	8,1 mm	
K ₅	M4	



Dimensions

F _W	20 mm	Diameter of ball complement
H ₂	25 mm	Axis center
Tol H ₂	± 0,015 mm	Tolerance