



IMAGE
COMING SOON





KGHK14-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

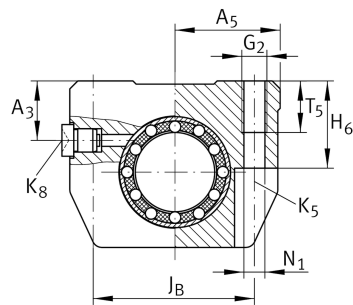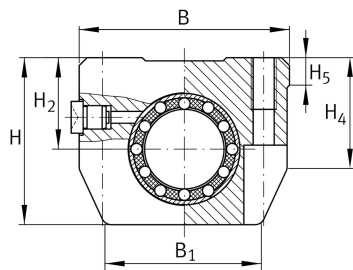


Your current product variant

Size code	14
Version	B
Seal	PP
Relubrication feature	AS

Main Dimensions & Performance Data

F _W	14 mm	Diameter of ball complement
H	36,5 mm	Height
L	28,2 mm	Length
B	43 mm	Width
C	690 N	Dynamic load rating
C ₀	520 N	Basic static load capacity
≈m	0,1 kg	Weight

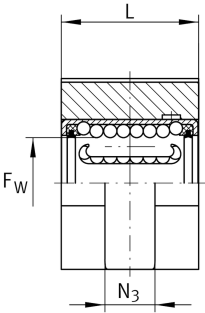

Mounting dimensions

J B	34 mm	
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	34 mm	
A 5	21,5 mm	
H 2	18 mm	Center height
Tol H 2	+ 0,01 mm	Upper tolerance
Tol H 2	- 0,014 mm	Lower tolerance
H 4	28,1 mm	Mounting Dimension
H 5	6,9 mm	
T 5	11 mm	
H 6	18 mm	Mounting Dimension
A 3	13 mm	
G 2	M5	
N 1	4,3 mm	
N 3	10 mm	
K 5	M4	
K 8	NIPA1	Lubrication nipple