



IMAGE
COMING SOON





KGHK40-B-PP-AS

Linear Ball Bearing and Housing Unit

Linear ball bearing and housing unit; sealed, greased, with relubrication facility; corrosion-resistant design possible

Technical information

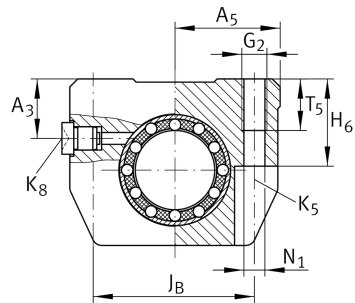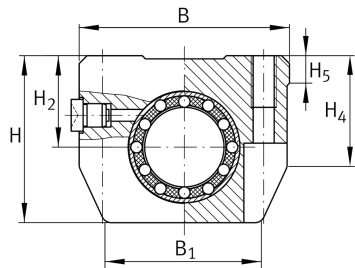

Your current product variant

Size code	40
Version	B
Seal	PP
Relubrication feature	AS

Main Dimensions & Performance Data


F _W	40 mm	Diameter of ball complement
H	73,5 mm	Height
L	60,2 mm	Length
B	87 mm	Width
C	5.300 N	Dynamic load rating
C ₀	4.450 N	Basic static load capacity
≈m	0,759 kg	Weight



View product details on medias

05.08.2026, 22:35:13 UTC

SCHAEFFLER

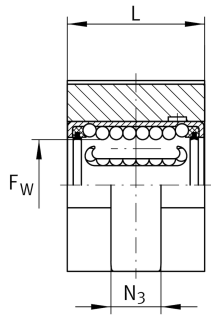

Mounting dimensions

J B	69 mm	
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	63 mm	
A 5	43,5 mm	
H 2	39 mm	Center height
Tol H 2	+ 0,01 mm	Upper tolerance
Tol H 2	- 0,014 mm	Lower tolerance
H 4	49,7 mm	Mounting Dimension
H 5	12,8 mm	
T 5	22 mm	
H 6	38 mm	Mounting Dimension
A 3	23 mm	
G 2	M10	
N 1	8,4 mm	
N 3	18 mm	
K 5	M8	
K 8	NIPA2	Lubrication nipple